

CGL 125


Level Probes / Conductive Level Sensors

Max 10 Bar /Max 180°C

Connection 3/8"G

Diameter 5,8 or 8 mm (check item codes listed below)

Length from 30 to 100 cm (check item codes listed below)

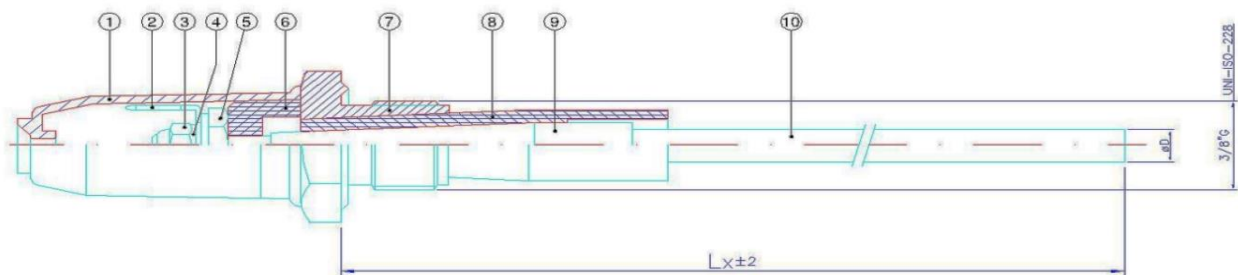

- 1) Rubber Protection (EPDM) (not in picture)
- 2) Faston 6.3 (AISI 304)
- 3) Self-blocking Dice (Fe/Zn 8c1B)
- 4) Grower Washer (Fe/Zn 8c1B)
- 5) Lock Nut (Galvanized AVP)
- 6) Cylindrical Insulator (PTFE G400)
- 7) External Body 3/8" (AISI 303)
- 8) Conical Insulator (PTFE G400)
- 9) Electrode Holder (Galvanized AVP or AISI 304) (check item codes listed below)
- 10) Electrode (AISI 304)



ITEM CODES

CGL 125-S 4/8 Diameter Electrode 8mm

67011111	CGL125-3S4/8	(30cm)
67011121	CGL125-5S4/8	(50cm)
67011131	CGL125-7S4/8	(70cm)
67011136	CGL125-8S4/8	(80cm)
67011141	CGL125-10S4/8	(100cm)

CGL 125-S4 Electrode Holder (Galvanized AVP)

67011110	CGL125-3S4	(30cm)
67011120	CGL125-5S4	(50cm)
67011130	CGL125-7S4	(70cm)
67011140	CGL125-10S4	(100cm)

CGL 125-SS4 Electrode Holder (AISI 304)

67011112	CGL125-3SS4	(30cm)
67011122	CGL125-5SS4	(50cm)
67011132	CGL125-7SS4	(70cm)
67011139	CGL125-10SS4	(100cm)